


## Technical data sheet Threaded rod

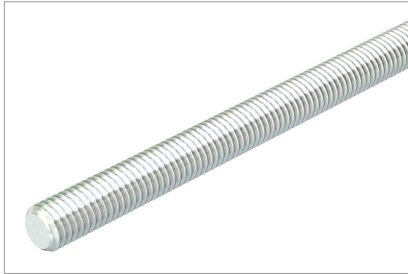


Threaded rod to DIN 976.

Type	Thread	Dimension d mm	Dimension L mm	Pack. pcs	Weight kg/100 pcs.	Art.-No.
2078 M8 1M V2A	M8	8	1000	50	30.000	3141310
2078 M10 1M V2A	M10	10	1000	25	49.000	3141312
2078 M12 1M V2A	M12	12	1000	20	70.000	3141314

**VA** Stainless steel, grade 304

/100

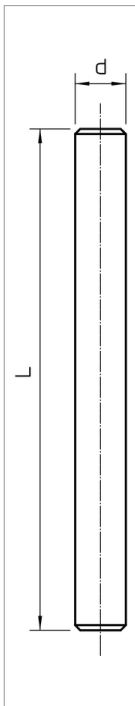

CE