


Cover for variable Magic bend

Cover for the variable bend, adjustable to an angle of 0 to 90°, locking through turn buckle and through overlapping with cable tray cover.



Dimensions

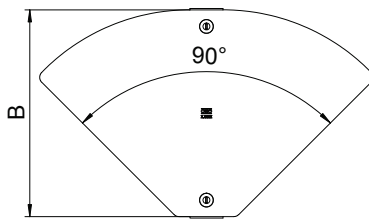

Type	Width mm	Plate thickness mm	Pack. pcs	Weight kg/100 pcs.	Item No.
DFBMV 100 FS	100	1	1	14,200	6040760
DFBMV 150 FS	150	1	1	24,900	6040762
DFBMV 200 FS	200	1	1	38,700	6040764
DFBMV 300 FS	300	1	1	75,500	6040766
DFBMV 400 FS	400	1,25	1	155,500	6040768
DFBMV 500 FS	500	1,25	1	232,300	6040770
DFBMV 600 FS	600	1,25	1	324,600	6040772
DFBMV 100 DD	100	1	1	14,200	6040780
DFBMV 200 DD	200	1	1	38,700	6040784
DFBMV 300 DD	300	1	1	75,500	6040786
DFBMV 400 DD	400	1,25	1	155,500	6040788
DFBMV 500 DD	500	1,25	1	232,300	6040790
DFBMV 600 DD	600	1,25	1	324,600	6040792
DFBMV 100 VA4301	100	1	1	16,800	6040800
DFBMV 150 VA4301	150	1	1	27,500	6040802
DFBMV 200 VA4301	200	1	1	41,300	6040804
DFBMV 300 VA4301	300	1	1	78,100	6040806
DFBMV 400 VA4301	400	1,25	1	158,100	6040808
DFBMV 500 VA4301	500	1,25	1	234,900	6040810
DFBMV 600 VA4301	600	1,25	1	327,200	6040812
DFBMV 100 VA4571	100	1	1	16,800	6040820
DFBMV 150 VA4571	150	1	1	27,500	6040822
DFBMV 200 VA4571	200	1	1	41,300	6040824
DFBMV 300 VA4571	300	1	1	78,100	6040826
DFBMV 400 VA4571	400	1,25	1	158,100	6040828
DFBMV 500 VA4571	500	1,25	1	234,900	6040830
DFBMV 600 VA4571	600	1,25	1	327,200	6040832

St Steel **V2A** Stainless steel, grade 304 **V4A** Stainless steel, grade 316 Ti

FS Strip-galvanised **DD** Strip galvanised zinc/aluminium, Double Dip