

Chalfant Cable Tray Systems

LADDER TRAY

Dimensions:

Rail Heights from 4" (45mm) - 10" (254mm)
Widths from 6" (150mm) - 48" (1219mm)
Rung Spacing from 6" (150mm) - 18" (457mm)
Lengths: 10' (3M), 12' (3.6M), 20' (6M)
24' (7.3M), 30' (9.1M), 40' (12.2M)

Finishes/Material:

Aluminum
Strip Galvanized (Mill)
Hot-Dip Galvanized
.304 & .316* Stainless Steel
Powder Coated

Features:

Built to NEMA VE2 Specifications.
Multiple side rail designs for light, medium duty, and long span applications.


Accessories:

Complete line of fittings and accessories.

Great for use in:

For commercial and industrial projects, our solutions ensure reliable support across a wide variety of applications, making installations efficient, cost-effective, and dependable.

*Steel Trays are offered in 4", 5", and 6" rail heights and in 10', 12', 20', and 24' lengths only.

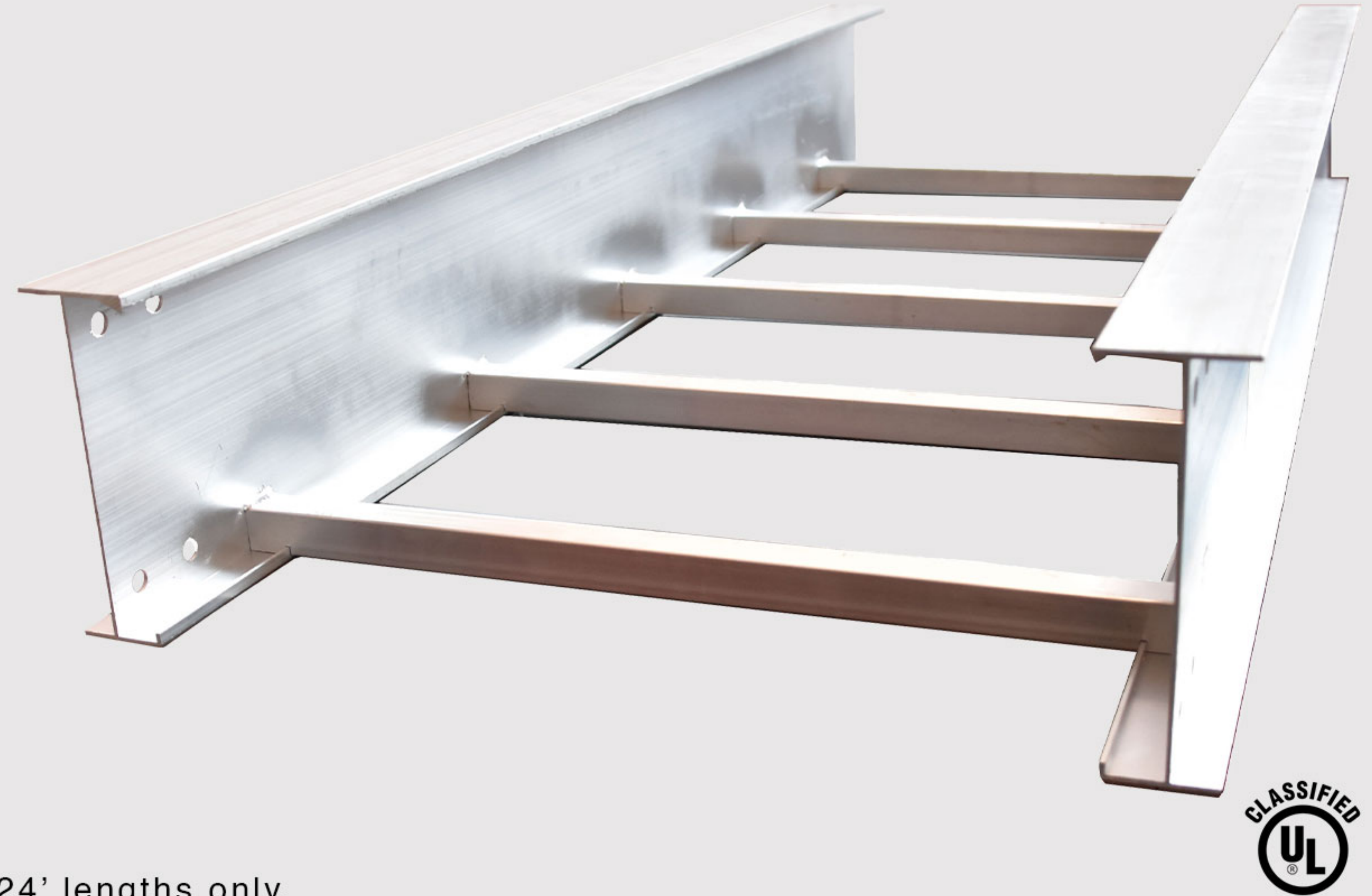

GR-MAGIC® CABLE TRAY

Dimensions:

Rail Heights from 1" (35mm) - 6" (155mm)*
Widths from 2" (50mm) - 24" (600mm)
Lengths: 10' (3M)

Finishes/Material:

Electroplated
Hot-Dip Galvanized
.304 & .316* Stainless Steel
Powder Coated

Features:

Self-Connecting GR-Magic® requires no additional connection hardware.
Light weight, easy to install and modify in the field.

Accessories:

Complete line of support brackets and hardware including kits to create bends and intersections in the field.

Great for use in:

Locations with low voltage, telecommunications and fiber optic cables on short spans.



*6" side height is not self connecting.

RKS-MAGIC® CABLE TRAY

Dimensions:

Rail Heights from 1" (35mm) - 2" (60mm)
Widths from 2" (50mm) - 24" (600mm)
Lengths: 10' (3M)

Finishes/Material:

Aluminum
Strip Galvanized (Mill)
Hot-Dip Galvanized
.304 & .316* Stainless Steel
Powder Coated

Features:


Self-Connecting RKS-Magic® requires no additional connection hardware.
Solid and ventilated styles.

Accessories:

Complete line of self-connecting bends, tees, intersections, dividers, covers, connectors, and blind ends.

Great for use in:

Applications where cable protection and maintaining aesthetics are important.

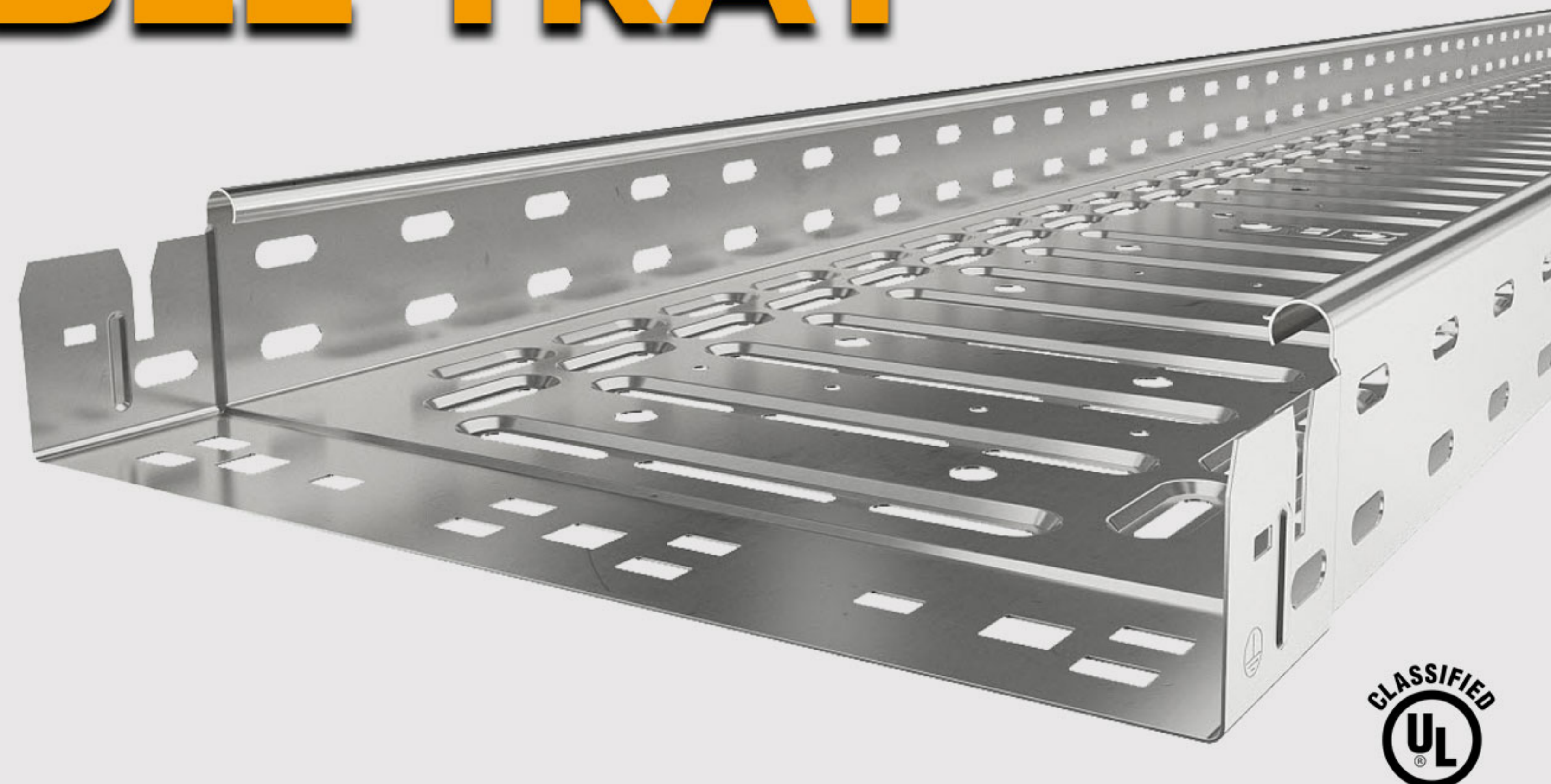

Chalfant Cable Tray Systems

SERIES 6 TROUGH TRAY



Dimensions:

Rail Heights from 3" (76mm) - 6" (152mm)
Widths from 6" (152mm) - 24" (610mm)
Lengths: 10' (3M), 12' (3.6M)

Finishes/Material:

Aluminum
Strip Galvanized (Mill)
Hot-Dip Galvanized
.304 & .316* Stainless Steel
Powder Coated

Features:

Built to NEMA Standards.
Light weight, solid and ventilated styles.

Accessories:

Complete line of fittings and accessories.

Great for use in:

Locations where protecting cables and maintaining aesthetics is important.

BKRS WALKABLE CABLE TRAY

Dimensions:

Rail Heights 4" (100mm and 110mm)
Widths from 4" (100mm) - 24" (600mm)
Lengths: 10' (3M)

Finishes/Material:

Strip Galvanized (Mill)

Features:


Tray and cover system designed to support heavy loads, stamping feet, and more.

Accessories:

Floor mount supports, connectors, dividers, and dust protection.

Great for use in:

Industrial and automation locations to protect power and data cables across the floor.

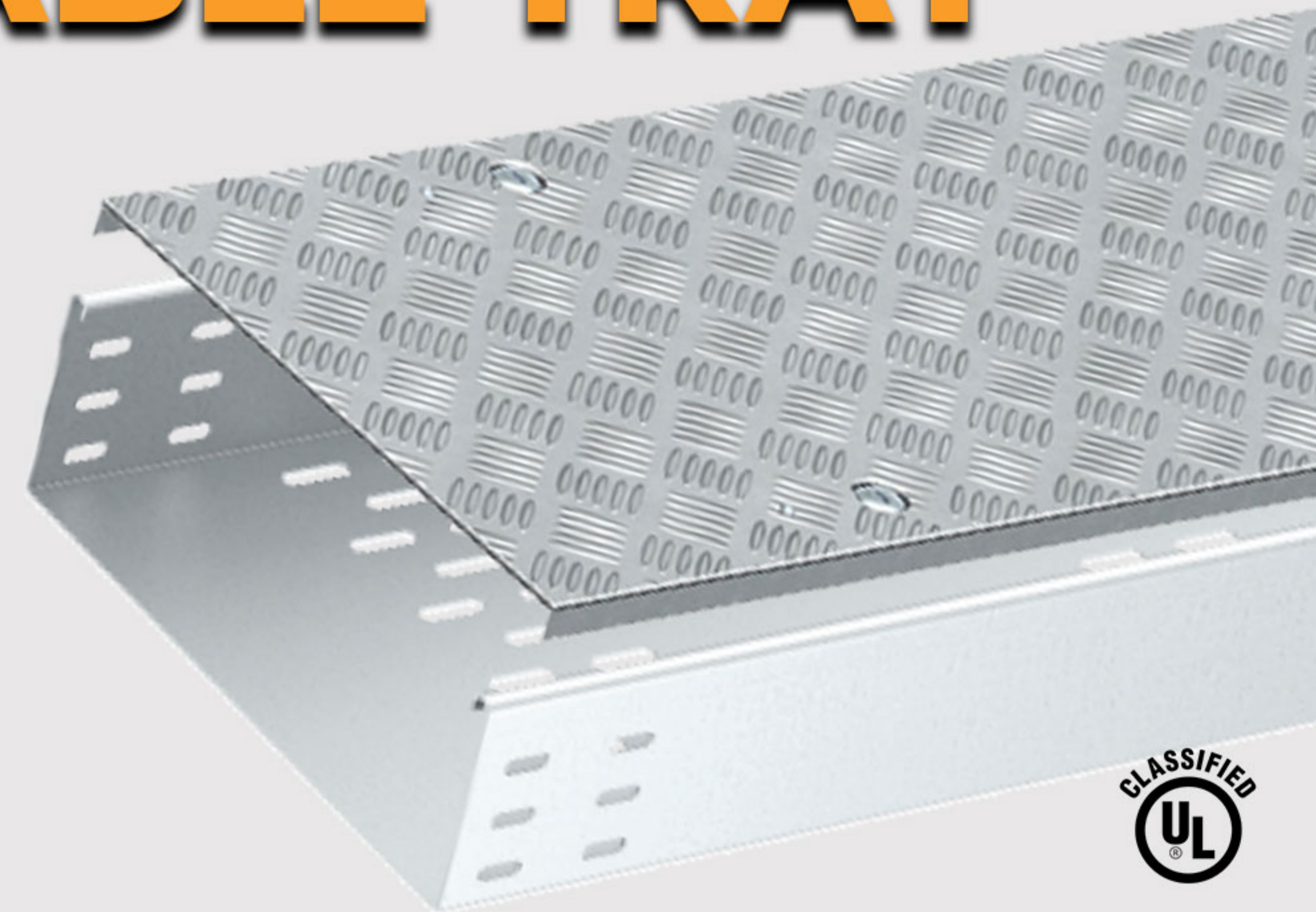

**Visit our
website to
find a
sales rep
near you!**